


**B 51012**

**Cage nuts**

Strength class 4

Steel 4 | zinc-plated | Cr(VI)-free | Metric thread

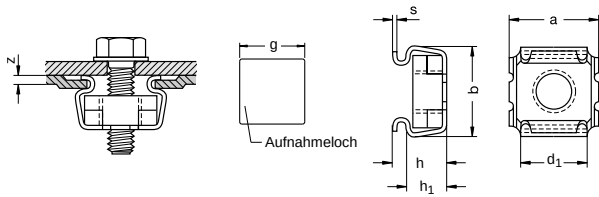

| Diameter<br>(d) | a<br>nominal size | b<br>nominal size | d <sub>1</sub><br>nominal size | g<br>nominal size | h <sub>1</sub><br>nominal size | h<br>nominal size | s<br>nominal size | Pitch<br>(P) | z         |
|-----------------|-------------------|-------------------|--------------------------------|-------------------|--------------------------------|-------------------|-------------------|--------------|-----------|
| M4              | 13.2              | 13.5              | 8.2                            | 9.5 x 9.5         | 6                              | 8.7               | 0.5               | 0.7          | 0.7 - 1.6 |
| M5              | 13.2              | 13.5              | 8.2                            | 9.5 x 9.5         | 6                              | 8.7               | 0.5               | 0.8          | 0.7 - 1.6 |
| M6              | 13.2              | 13.5              | 8.2                            | 9.5 x 9.5         | 6                              | 8.7               | 0.5               | 1.0          | 0.7 - 1.6 |

All technical data refer to the measure mm

