


B 52005

AMTEC® screws

Ccountersunk head | cross-slot pozidriv

Steel 10 | zinc-plated | Cr(VI)-free | Self-tapping thread

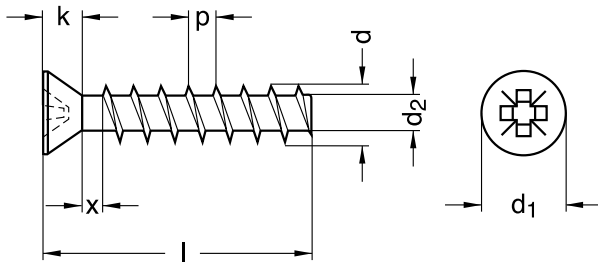

Diameter (d)	d ₁		d ₂		k nominal size	Pitch (P)	x max.	Tool size
	nominal size	nominal size	min.	max.				
2.5	4.7	1.6	1.5	1.7	1.70	1.12	2.2	Z1
3	5.5	2	1.9	2.1	1.80	1.35	2.8	Z1
3.5	7.3	2.2	2.1	2.3	2.56	1.60	3.2	Z2
4	8.4	2.4	2.3	2.5	2.90	1.80	3.6	Z2
5	9.3	2.9	2.8	3.0	3.00	2.20	4.6	Z2

nominal size	Length (l)	
	min.	max.
8	7.25	8.75
10	9.25	10.75

nominal size	Length (l)	
	min.	max.
12	11.10	12.90
16	15.10	16.90
20	18.95	21.05

Diameter (d)	Length (l)				
	8	10	12	16	20
2.5	●				
3	●	●	●	●	
3.5			●		
4			●	●	
5					●

• Combinations available in the eShop | Other sizes on request

All technical data refer to the measure mm

