


**B 52030**  
**QUICK FLOW® thin sheet screw**

Button head | hexalobular drive | anti-friction coated

Steel | zinc-plated, thick-film passivated (VZD) | Cr(VI)-free | Self-tapping thread

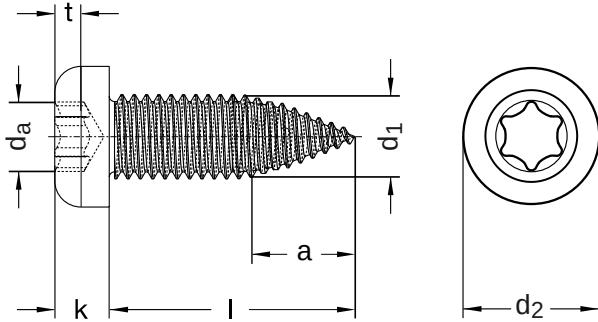

Diameter (d)	a max.	d <sub>1</sub> nominal size	d <sub>2</sub> nominal size	d <sub>a</sub> nominal size	k nominal size	Pitch (P)	t		Tool size
							max.	min.	
M4	7.0	4	8	3.95	3.1	0.7	1.66	1.27	T20
M5	9.0	5	9.5	4.50	3.7	0.8	1.91	1.52	T25
M6	10.5	6	12	5.60	4.6	1.0	2.42	2.02	T30

nominal size	Length (l)	
	min.	max.
12	11.7	12.3
17	16.6	17.4
20	19.6	20.4
28	27.5	28.5

Diameter (d)	Length (l)			
	12	17	20	28
M4	●	●		
M5		●	●	
M6			●	●

• Combinations available in the eShop | Other sizes on request

All technical data refer to the measure mm

