
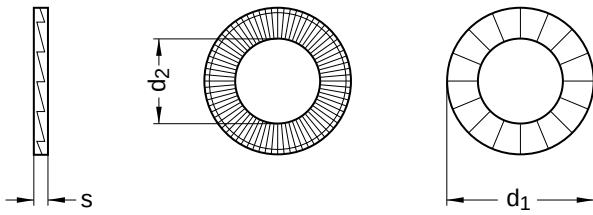


B 53074
NORD-LOCK® wedge-locking washers

Enlarged outer diameter

Stainless steel A4 | bright | Cr(VI)-free

Further information: Laser marking with lot number | For further information and CAD-files please use the link to NORD-LOCK® homepage: <http://www.solidcomponents.com/?company=SCCAD48YT>

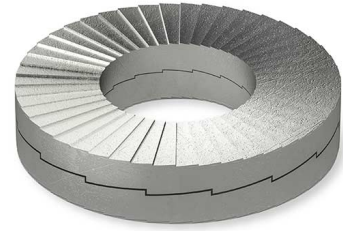

Diameter (d)	d ₁			d ₂			s			Pitch (P)
	nominal size	min.	max.	nominal size	min.	max.	nominal size	min.	max.	
M4	9	8.8	9.2	4.4	4.3	4.5	2.2	1.95	2.45	0.70
M5	10.8	10.6	11.0	5.4	5.3	5.5	2.2	1.95	2.45	0.80
M6	13.5	13.3	13.7	6.5	6.4	6.6	2.0	1.75	2.25	1.00
M8	16.6	16.4	16.8	8.7	8.6	8.8	2.0	1.75	2.25	1.25
M10	21	20.8	21.2	10.7	10.5	10.9	2.0	1.75	2.25	1.50
M12	25.4	25.2	25.6	13	12.8	13.2	3.0	2.75	3.25	1.75
M14	30.7	30.5	30.9	15.2	15.0	15.4	3.2	2.95	3.45	2.00
M16	30.7	30.5	30.9	17	16.8	17.2	3.2	2.95	3.45	2.00
M18	34.5	34.3	34.7	19.5	19.3	19.7	3.2	2.95	3.45	2.50
M20	39	38.8	39.2	21.4	21.2	21.6	3.2	2.95	3.45	2.50
M22	42	41.8	42.2	23.4	23.2	23.6	3.2	2.95	3.45	2.50
M24	48.5	48.3	48.7	25.3	25.1	25.5	4.5	4.25	4.75	3.00
M27	48.5	48.2	48.8	28.4	28.2	28.6	6.8	6.30	–	3.00
M30	58.5	58.2	58.8	31.4	31.2	31.6	6.8	6.30	–	3.50

All technical data refer to the measure mm

