


DIN 11024

Spring cotter

Simple twist

Spring steel | zinc-plated | Cr(VI)-free

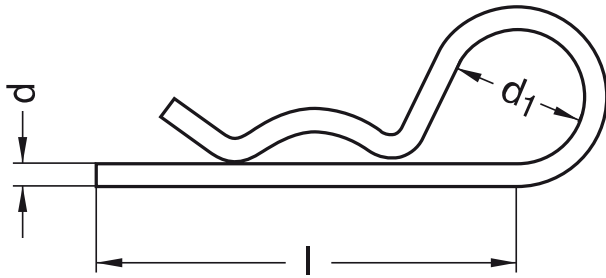

Diameter (d)	d ₁ nominal size	Length (l) nominal size
2	10	50
3	16	62
4	23	78
5	26	92
6	30	120
7	30	130
8	30	130

All technical data refer to the measure mm

