


**DIN 431**

**Pipe nuts**

With pipe thread | form B

Stainless steel A2 | Cr(VI)-free | Pipe thread

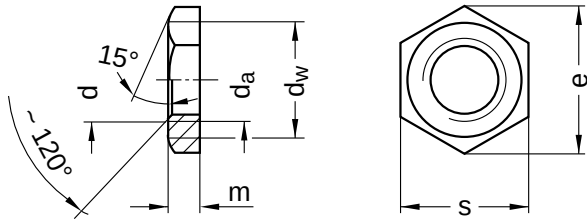

Diameter (d)	d <sub>a</sub>		e	m		s		Tool size
	max.	min.		min.	max.	min.	max.	
G 1/8	10.5	16.5	19.85	6	6.48	17.57	18	SW 18
G 1/4	14.2	19.1	22.78	6	6.48	20.16	21	SW 21
G 3/8	18.0	24.8	29.56	7	7.58	26.16	27	SW 27
G 1/2	22.6	31.3	37.29	8	8.58	33.00	34	SW 34
G 5/8	24.7	31.3	37.29	8	8.58	33.00	34	SW 34
G 3/4	28.6	32.3	39.55	9	9.58	35.00	36	SW 36
G 7/8	32.6	38.0	45.20	9	9.58	40.00	41	SW 41
G 1	35.6	42.8	50.85	10	10.58	45.00	46	SW 46
G 1 1/4	45.3	51.1	60.79	11	11.70	53.80	55	SW 55
G 1 1/2	51.6	55.9	66.44	12	12.70	58.80	60	SW 60

All technical data refer to the measure mm

