


**DIN 603**

**Mushroom head bolts**

With square neck | without nut

Steel 8.8 | zinc-plated, thick-film passivated (VZD) | Cr(VI)-free | Metric thread

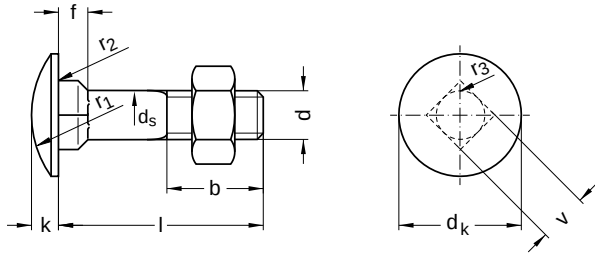

Diameter (d)	b			dk		ds		f	
	l up to 125	l up to 200	l longer than 200	min.	max.	min.	max.	min.	max.
M6	18	24	–	15.45	16.55	5.52	6	3.40	4.60
M8	22	28	41	19.35	20.65	7.42	8	4.40	5.60
M10	26	32	45	23.35	24.65	9.42	10	5.40	6.60
M12	30	36	49	29.35	30.65	11.30	12	7.25	8.75
M16	38	44	57	37.20	38.80	15.30	16	11.10	12.90

Diameter (d)	k		r1	r2	r3	Pitch (P)	v	
	min.	max.	nominal size	nominal size	max.		min.	
M6	3.12	3.88	12.6	0.5	0.9	1.00	6.48	5.52
M8	4.12	4.88	16.0	0.5	1.2	1.25	8.58	7.42
M10	4.62	5.38	19.2	0.5	1.5	1.50	10.58	9.42
M12	6.05	6.95	24.1	1.0	1.8	1.75	12.70	11.30
M16	8.05	8.95	29.3	1.0	2.4	2.00	16.70	15.30

nominal size	Length (l)	
	min.	max.
16	15.10	16.90
20	18.95	21.05
25	23.95	26.05
30	28.95	31.05
35	33.75	36.25
40	38.75	41.25

nominal size	Length (l)	
	min.	max.
45	43.75	46.25
50	48.75	51.25
55	53.50	56.50
60	58.50	61.50
65	63.50	66.50
70	68.50	71.50

nominal size	Length (l)	
	min.	max.
75	73.50	76.50
80	78.50	81.50
90	88.25	91.75
100	98.25	101.75
110	108.25	111.75
120	118.25	121.75

All technical data refer to the measure mm



**DIN 603**

**Mushroom head bolts**

With square neck | without nut

Steel 8.8 | zinc-plated, thick-film passivated (VZD) | Cr(VI)-free | Metric thread

Diameter (d)	Length (l)																	
	16	20	25	30	35	40	45	50	55	60	65	70	75	80	90	100	110	120
M6	●	●	●	●	●	●		●										
M8	●	●	●	●	●	●	●	●	●	●		●		●				
M10		●	●	●	●	●	●	●	●	●	●	●	●	●	●	●		
M12			●	●	●	●	●	●	●		●	●	●	●	●	●	●	●
M16					●		●	●	●							●		

• Combinations available in the eShop | Other sizes on request

All technical data refer to the measure mm

