



DIN 7504 O similar to ISO 15482

Self-drilling screws

Form O: countersunk head according to DIN ISO 7050 | cross-slot phillips | with wings and ribs

Steel | zinc-plated | Cr(VI)-free | Thread type ST (sheet metal)

Further information: DIN-standard has been withdrawn

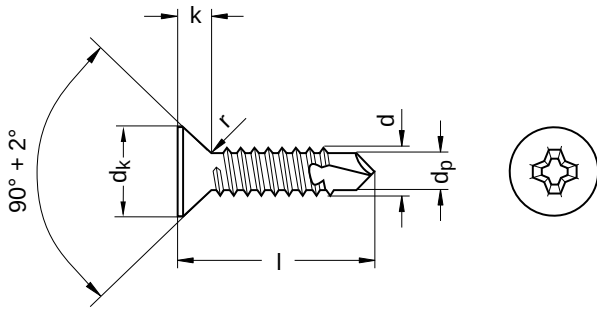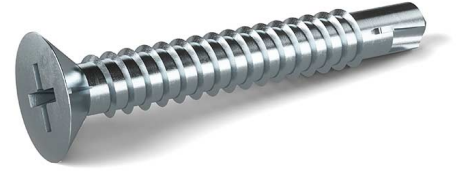

Diameter (d)	Drilling range starting	Sheet metal thickness up to	d _k		d _p max.	k max.	r max.	Tool size
			min.	max.				
6.3	2	6	10.9	11.3	5.8	3.15	2.4	H3

nominal size	Length (l)	
	min.	max.
45	43.75	46.25
50	48.75	51.25

Diameter (d)	Length (l)	
	45	50
6.3	●	●

• Combinations available in the eShop | Other sizes on request

All technical data refer to the measure mm

