


**DIN 84** identical with ISO 1207

## Cylinder screws

Slotted

Steel 4.8 | zinc-plated | Cr(VI)-free | Metric thread

Further information: DIN standard has been withdrawn

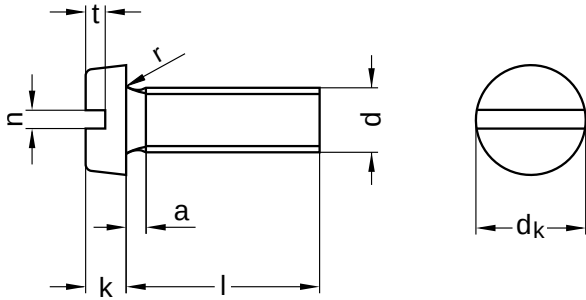

Diameter (d)	a max.	d <sub>k</sub>		k		n			r min.	Pitch (P)	t min.
		min.	max.	min.	max.	nominal size	min.	max.			
M2	0.8	3.62	3.8	1.16	1.3	0.5	0.56	0.70	0.10	0.40	0.60
M2.5	0.9	4.32	4.5	1.46	1.6	0.6	0.66	0.80	0.10	0.45	0.70
M3	1.0	5.32	5.5	1.86	2.0	0.8	0.86	1.00	0.10	0.50	0.85
M3.5	1.2	5.82	6.0	2.26	2.4	1.0	1.06	1.20	0.10	0.60	1.00
M4	1.4	6.78	7.0	2.46	2.6	1.2	1.26	1.51	0.20	0.70	1.10
M5	1.6	8.28	8.5	3.12	3.3	1.2	1.26	1.51	0.20	0.80	1.30
M6	2.0	9.78	10.0	3.60	3.9	1.6	1.66	1.91	0.25	1.00	1.60
M8	2.5	12.73	13.0	4.70	5.0	2.0	2.06	2.31	0.40	1.25	2.00
M10	3.0	15.73	16.0	5.70	6.0	2.5	2.56	2.81	0.40	1.50	2.40

nominal size	Length (l)	
	min.	max.
3	2.80	3.20
4	3.76	4.24
5	4.76	5.24
6	5.76	6.24
8	7.71	8.29
10	9.71	10.29
12	11.65	12.35
14	13.65	14.35
16	15.65	16.35
18	17.65	18.35
20	19.58	20.42
22	21.58	22.42

nominal size	Length (l)	
	min.	max.
25	24.58	25.42
28	27.58	28.42
30	29.58	30.42
35	34.50	35.50
40	39.50	40.50
45	44.50	45.50
50	49.50	50.50
55	54.05	55.95
60	59.05	60.95
65	64.05	65.95
70	69.05	70.95
80	79.05	80.95

All technical data refer to the measure mm



**DIN 84** identical with ISO 1207

## Cylinder screws

Slotted

Steel 4.8 | zinc-plated | Cr(VI)-free | Metric thread

Diameter (d)	Length (l)																								
	3	4	5	6	8	10	12	14	16	18	20	22	25	28	30	35	40	45	50	55	60	65	70	80	
M2	●	●	●	●	●	●	●	●	●		●														
M2.5	●	●	●	●	●	●	●	●	●	●	●		●												
M3		●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●						
M3.5			●	●		●	●		●		●		●		●										
M4		●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
M5				●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
M6				●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
M8						●	●		●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
M10									●		●		●		●		●		●	●	●	●	●	●	●

• Combinations available in the eShop | Other sizes on request

All technical data refer to the measure mm

