


**DIN 911** similar to ISO 2936

## Hexagon socket screw key

For hexagon socket screws DIN 912, 7984 and 7991 respectively threaded pins ISO 4026-4029

Steel 10.9 | bright | Cr(VI)-free

Further information: DIN-standard has been withdrawn

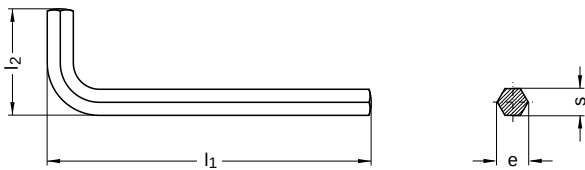

Diameter (d)	e		l <sub>1</sub>	l <sub>2</sub>	nominal size	s		Tool size
	max.	min.				min.	max.	
SW 1.5	1.68	1.63	45	14	1.5	1.52	1.54	SW 1,5
SW 2	2.25	2.18	50	16	2.0	2.02	2.04	SW 2
SW 2.5	2.82	2.75	56	18	2.5	2.52	2.56	SW 2,5
SW 3	3.39	3.31	63	20	3.0	3.02	3.08	SW 3
SW 4	4.53	4.44	70	25	4.0	4.02	4.10	SW 4
SW 5	5.67	5.58	80	28	5.0	5.02	5.10	SW 5
SW 6	6.81	6.71	90	32	6.0	6.02	6.10	SW 6
SW 7	7.95	7.84	95	34	7.0	7.02	7.12	SW 7
SW 8	9.09	8.97	100	36	8.0	8.02	8.12	SW 8
SW 10	11.37	11.23	112	40	10.0	10.02	10.12	SW 10
SW 12	13.65	13.44	125	45	12.0	12.03	12.14	SW 12
SW 14	15.93	15.70	140	56	14.0	14.03	14.14	SW 14
SW 17	19.35	19.09	160	63	17.0	17.05	17.23	SW 17
SW 19	21.63	21.32	180	70	19.0	19.06	19.28	SW 19
SW 22	25.05	24.71	200	80	22.0	22.06	22.28	SW 22
SW 27	30.75	30.36	250	100	27.0	27.08	27.28	SW 27

All technical data refer to the measure mm

