


DIN 965 similar to ISO 7046

Countersunk bolts

Cross-slot pozidriv

Stainless steel A2 | Cr(VI)-free | Metric thread

Further information: DIN standard has been withdrawn

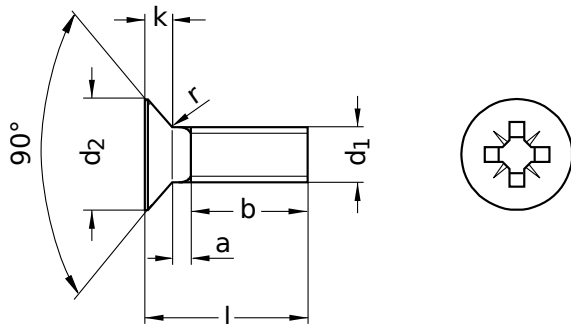

Diameter (d)	a max.	b nominal size	d ₁ nominal size	d ₂ nominal size	k max.	r max.	Pitch (P)	Tool size
M2	0.8	16	M2	3.8	1.20	0.5	0.40	Z1
M2.5	0.9	18	M 2.5	4.7	1.50	0.7	0.45	Z1
M3	1.0	19	M3	5.6	1.65	0.8	0.50	Z1
M4	1.4	22	M4	7.5	2.20	1.0	0.70	Z2
M5	1.6	25	M5	9.2	2.50	1.3	0.80	Z2
M6	2.0	28	M6	11	3.00	1.6	1.00	Z3

nominal size	Length (l)	
	min.	max.
5	4.75	5.25
6	5.75	6.25
8	7.70	8.30
10	9.70	10.30
12	11.65	12.35
14	13.65	14.35
16	15.65	16.35
18	17.65	18.35

nominal size	Length (l)	
	min.	max.
20	19.60	20.40
25	24.60	25.40
30	29.60	30.40
35	34.50	35.50
40	39.50	40.50
50	49.50	50.50

Diameter (d)	Length (l)													
	5	6	8	10	12	14	16	18	20	25	30	35	40	50
M2	●	●	●	●	●	●	●	●	●					
M2.5	●		●	●			●	●						
M3	●	●	●	●	●	●	●	●	●	●				
M4		●	●	●	●	●	●	●	●	●	●	●		
M5		●	●	●	●		●		●	●	●	●	●	
M6			●		●		●		●	●	●	●	●	●

• Combinations available in the eShop | Other sizes on request

All technical data refer to the measure mm

